

## Switches and Lighting Controls

### 15A 120V AC, Self Grounding

#### 1) Single Pole Toggle, 1) Single Receptacle

#### Features

- Quiet snap action mechanism
- Self-grounding staple is standard
- Elongated strap with continuous plaster ears
- Residential Grade

#### Ordering Information

|              |              |                       |
|--------------|--------------|-----------------------|
| <b>Color</b> | <b>UPC</b>   | <b>Catalog Number</b> |
| Ivory        | 883778109720 | RC108I                |


#### Listings

UL Listed

#### Specifications

|                          |   |
|--------------------------|---|
| Action                   | Snap Switch   |
| Contact Configuration    | Two Position  |
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means           |
| Operating Cycles         | 30,000 Minimum  |
| Operating Temperature    | Max Continuous- 60 Degrees C, Minimum- -20 Without Impact |
| Wattage                  | 1800  |

# HUBBELL

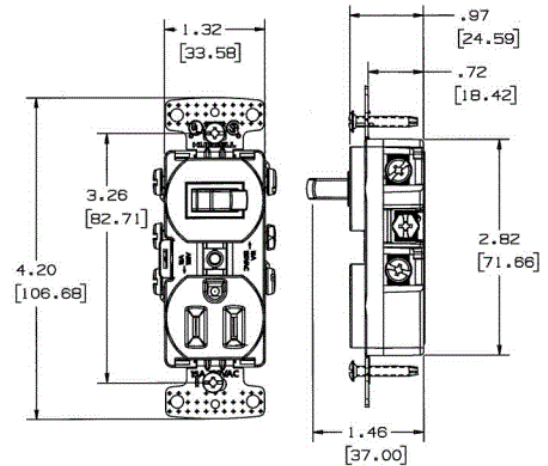

#### Online Resources

Customer Sales Drawings  
eCatalog  
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

