

Switches and Lighting Controls

15A 120V AC, Self Grounding

1) Three Way Toggle, 1) Single Tamper Resistant Receptacle

Features

- Quiet snap action mechanism
- Self-grounding staple is standard
- Elongated strap with continuous plaster ears
- Residential Grade

Ordering Information

UPC 883778302305 Catalog Number RC308ITR


Listings

UL Listed

Specifications

| | |
|--------------------------|---|
| Action | Snap Switch |
| Contact Configuration | Two Position |
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means |
| Operating Cycles | 30,000 Minimum |
| Operating Temperature | Max Continuous- 60 Degrees C, Minimum- -20 Without Impact |
| Wattage | 1800 |

HUBBELL

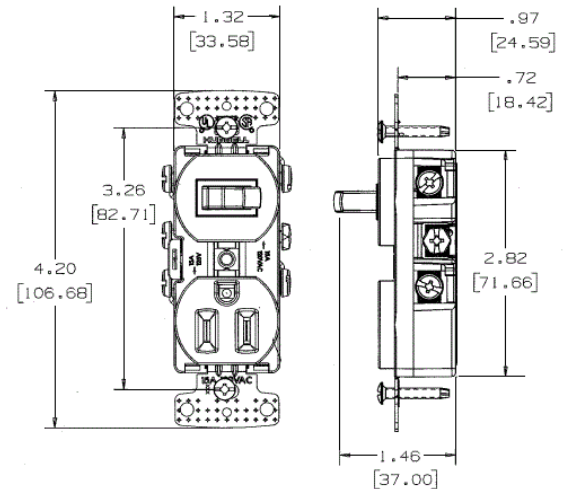

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

