

Switches and Lighting Controls

15A 120V AC, Self Grounding

1) Three Way Toggle, 1) Single Receptacle



Features

- Quiet snap action mechanism
- Self-grounding staple is standard
- Elongated strap with continuous plaster ears
- Residential Grade

Ordering Information


Color	UPC	Catalog Number
Ivory	883778109843	RC308I

Listings

UL Listed

Specifications

Action	Snap Switch
Contact Configuration	Two Position
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Operating Cycles	30,000 Minimum
Operating Temperature	Max Continuous- 60 Degrees C, Minimum- -20 Without Impact
Wattage	1800

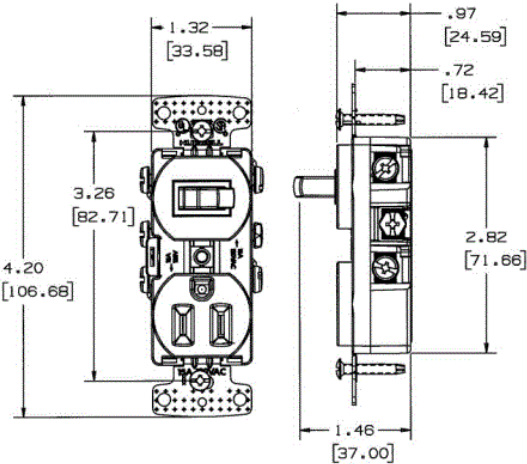

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

