

Switches and Lighting Controls

15A 120V AC, Self Grounding

1) Three Way Toggle, 1) Single Receptacle



Features

- Quiet snap action mechanism
- Self-grounding staple is standard
- Elongated strap with continuous plaster ears
- Residential Grade

Ordering Information


| | | |
|-------|--------------|----------------|
| Color | UPC | Catalog Number |
| Brown | 883778109836 | RC308 |

Listings

UL Listed

Specifications

| | |
|--------------------------|---|
| Action | Snap Switch |
| Contact Configuration | Two Position |
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means |
| Operating Cycles | 30,000 Minimum |
| Operating Temperature | Max Continuous- 60 Degrees C, Minimum- -20 Without Impact |
| Wattage | 1800 |

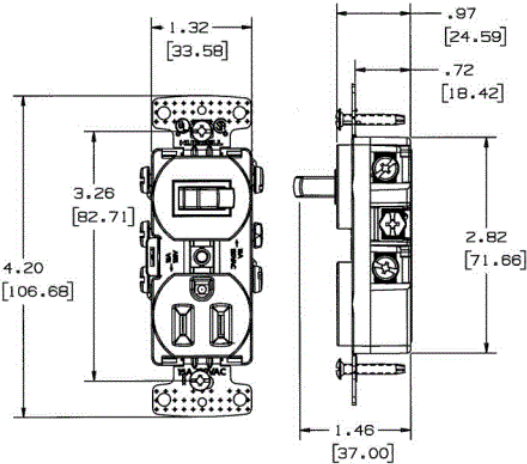

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

