

Load:Logic<sup>®</sup>

Room Controller

Specialty Switches - Dimmer



- Features
- Provides manual control of the room controller
  - Connects to room controller using standard UTP RJ45 patchcords
  - Predetermined cofiguration eliminates setup

Ordering Information

Description	Device Color	UPC Number	Catalog Number
2-Button; 1 Raise, 1 Lower	White	783585564524	RCSRLW

Listings


N/A

Specifications

Housing	Rugged, high-impact, injection-molded plastic
Dimensions	4.2" L x 1.60" W x 1.40" D

Performance

<b>Electrical</b>	
Addressing	8-position rotary switch
Power Requirements	24V DC
<b>Environmental</b>	
Operating Location	Indoor Use Only
Operating Temperature	0° to 40°C (32° to 104°F) Relative Humidity (non-condensing) 0% to 95%

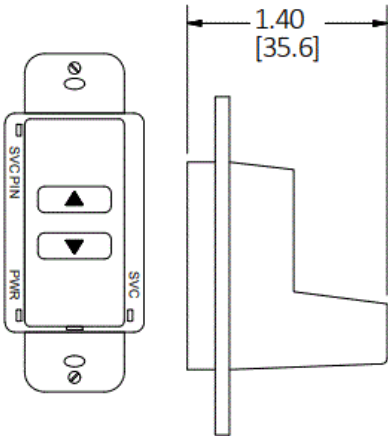

Complementary Products

Wallplate	NPS26W
Wallplate, Decorator Opening, Snap-on	NPS26W
Wallplate, Decorator Opening, Stainless Steel	SS26
Patch cord	NSC5EY25PNB

Online Resources

Customer Use Drawing  
eCatalog  
Installation Instructions

