

Residential Devices

15A 125V, 2-Pole 2-Wire Non-Grounding

Female Connector



Ordering Information


Color	UPC	Catalog Number
Black, White	883778112577	RP649

Listings

UL Listed

Specifications

Current/Amperage Rating	15 A
Voltage Rating	125 VAC
Application	Trade Select Residential Devices
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Insulation	Insulated Body
NEMA Rating	1-15R
Special Features	Polarized
Temperature Rating	Maximum Continuous: 75° C; Minimum Continuous: -40° C w/o impact, -25° with impact.

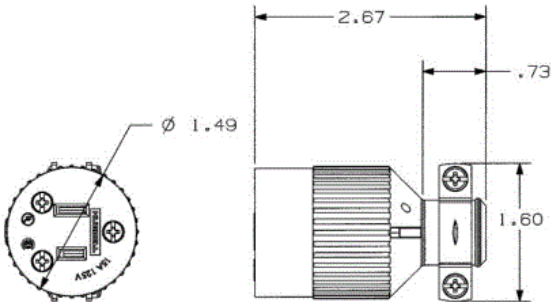

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

