

Residential Devices

15A 125V, 2-Pole 3-Wire

Single Receptacle



Features

- Panel cutout .95 x .95 inch (24.1 x 24.1 mm)
- Accommodate panel thickness of .031 to .062 inch (0.7 to 1.5 mm)

Ordering Information



| | | |
|-------|--------------|----------------|
| Color | UPC | Catalog Number |
| White | 883778304231 | RR374W |

Specifications

| | |
|--------------------------|---|
| Current/Amperage Rating | 15 A |
| Voltage Rating | 125 VAC |
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means |
| NEMA Rating | 5-15R |
| Phase | Single Phase |
| Wire Size | #16 AWG to #14 AWG |

Performance

| | |
|------------------------|---|
| Mechanical | |
| Terminal Accommodation | #14 AWG 6 inch AWM/TEW FT1 105°C 600V on black and white leads, #14 AWG 6 inch AWM/TEW FT1 600V on green lead |

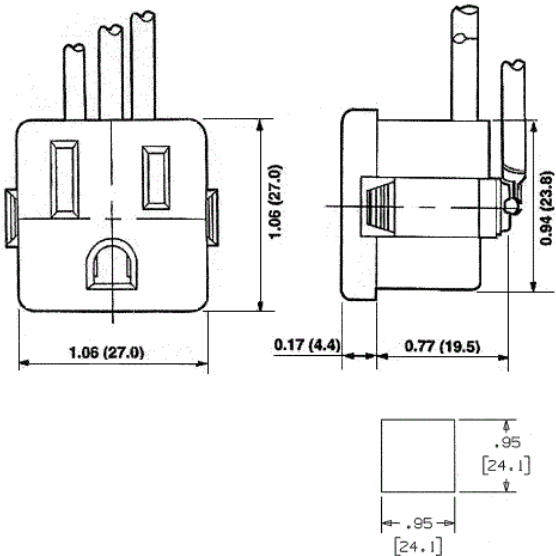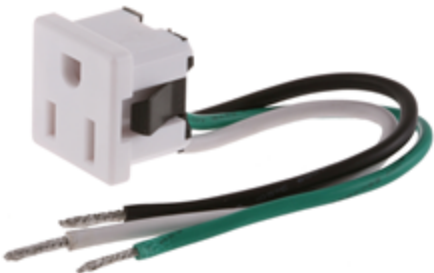

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

