

Residential Devices

15A 125V, 2-Pole 3-Wire

Single Receptacle



Features

- Panel cutout .95 x .95 inch (24.1 x 24.1 mm)
- Accommodate panel thickness of .031 to .062 inch (0.7 to 1.5 mm)

Ordering Information



Color	UPC	Catalog Number
Brown	883778304224	RR374

Specifications

Current/Amperage Rating	15 A
Voltage Rating	125 VAC
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
NEMA Rating	5-15R
Phase	Single Phase
Wire Size	#16 AWG to #14 AWG

Performance

Mechanical	
Terminal Accommodation	#14 AWG 6 inch AWM/TEW FT1 105°C 600V on black and white leads, #14 AWG 6 inch AWM/TEW FT1 600V on green lead

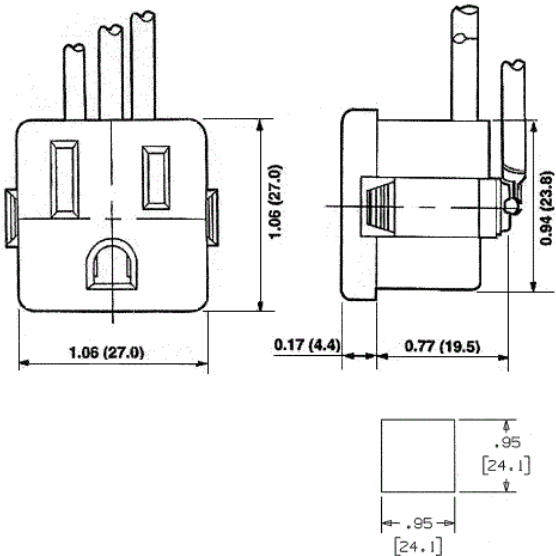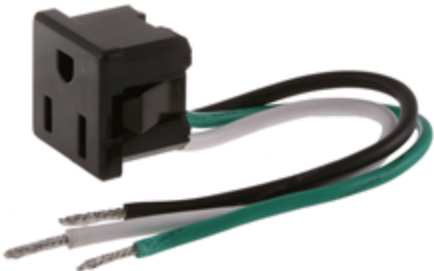

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

