

TradeSelect® Single Pole, 15A 120V AC, Three Way Switches and Lighting Controls

HUBBELL®

Features

- Hi-visibility yellow base for easy installation
- Elongated strap for easier wall box mounting
- Tough thermoplastic with ultrasonically welded cover and base
- Quiet snap action mechanism

Ordering Information

Description	UPC	Catalog Number
TradeSelect, Grounding, Push and Side Wire, 15A 120V AC, White	883778100932	RS315W

Listings


CSA Certified
UL Listed E3896

Specifications

Color	White nylon
-------	-------------

Performance

Max. Continuous Current	20 A
Max. Working Voltage	120V AC
Operating Temperature	Maximum continuous 60°C, minimum -20°C (without impact)

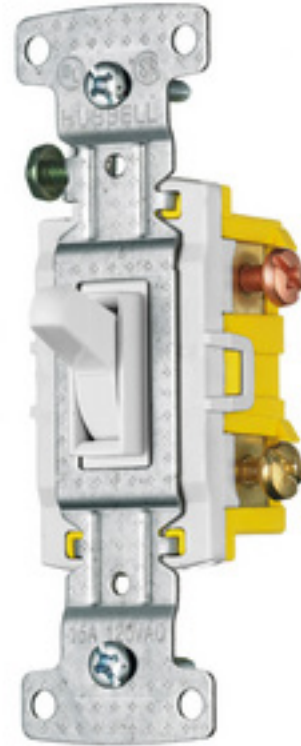

Links

[Installation Instructions](#)

[Media](#)

