

Switches, Four Way

15A, 120V AC

Residential Toggle Switch

Features

- Elongated strap for easier wall box mounting
- Tough thermoplastic with ultrasonically welded cover and base

Ordering Information

Description	Color	UPC Number	Catalog Number
Toggle, Self-Grounding, Push & Side Wire	Light Almond	883778119385	RS415LA

Listings

CSA Certified
UL Listed E3896

Specifications

Top Material	Plastic
Base Material	Plastic
Toggle Material	Plastic
Contacts	Silver Alloy
Terminal Screws	Brass
Auto Grounding Mounting Bridge	Zinc-Plated Steel
Ground Screw	Steel (Green)
Mounting Screw	Zinc-Plated Steel


Performance

Electrical	
Dielectric Voltage	Withstands 1500V AC minimum for 1 minute
Max. Continuous Current	15A
Max. Working Voltage	120V AC
Overload	Minimum 1.5 times rating
Temperature Rise	30°C maximum at rated current

Environmental

Flammability	UL 94 V-2
Operating Temperature	Maximum continuous 60°C; minimum -20°C (w/o impact)

HUBBELL

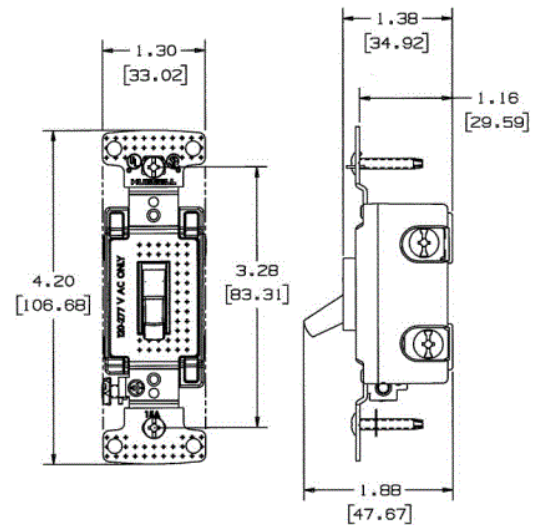

Online Resources

Customer Sales Drawing
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

