

Switches
20A 120/277V AC
 Style Line® Decorator Weatherproof Series

HUBBELL

Features

- NEMA Type 3R
- Single Pole / 3-Way Capable
- No cover required

Ordering Information

Description	Device Color	UPC	Catalog Number
Rocker, Weatherproof, Self-grounding, Back and side wired	Gray	883778309052	RSD120WPGY

Listings

cULus Listed

Specifications

Base and Body	Polycarbonate
Plate	Polycarbonate
Terminal Screws	Brass
Contacts	Silver Alloy
Movable Contact Arm	Copper Alloy

Performance


Electrical	
Dielectric Voltage	Withstands 1,500V AC minimum for 1 minute
Endurance	30,000 cycles minimum
Max. Working Voltage	120/277V
Overload	4.8 times rated current

Environmental

Weatherproof	3R Rated
Flammability	UL V2
Operating Temperatures	Maximum continuous 75°C minimum -40°C (without impact)

Mechanical

Terminal Accommodation	Back and side wire: #14 AWG min. - #10 AWG max. solid and stranded copper wire only
------------------------	---

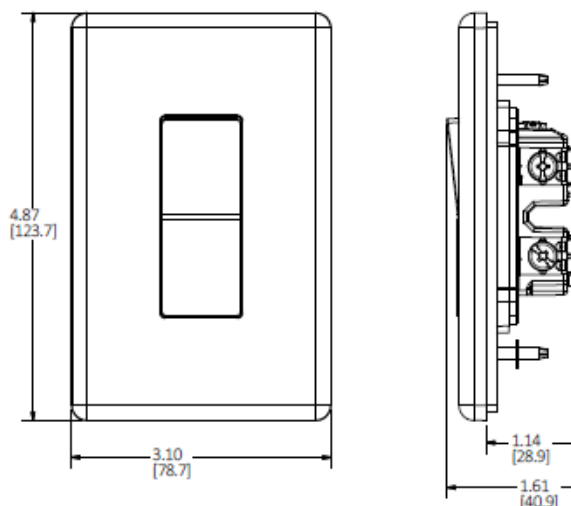

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

