

Switches and Lighting Controls

15A 120/277V AC, Double Pole

Rocker

HUBBELL

Features

- Smooth, quiet rocker
- Self-grounding feature is standard
- Ultrasonically welded cover and base
- Residential Grade

Ordering Information


Color	UPC	Catalog Number
Gray	883778101397	RSD215GY

Listings

CSA Certified
UL Listed E3896

Performance

Electrical	
Dielectric voltage	Withstands 1,500V AC minimum for 1 minute
Endurance	30,000 cycles minimum
Max. working voltage	120V
Overload	1.5 times rating
Mechanical	
Terminal accommodation	Back and side wire: #14 AWG min. - #12 AWG max. solid and stranded copper wire only; push wire: #14 AWG solid copper wire only
Environmental	
Flammability	UL V-0
Operating Temperatures	Maximum continuous 60°C; minimum -20°C (without impact)

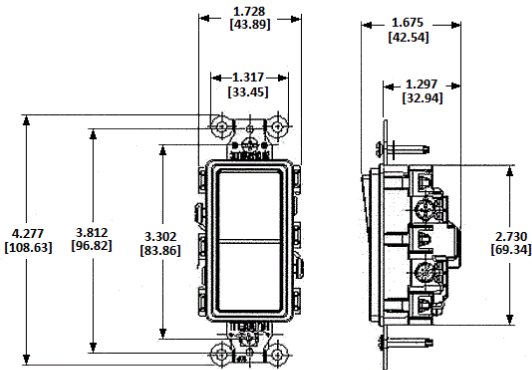

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

