

## Single Pole Devices and Temporary Power

50A, 120/240V AC

## Spider® II Temporary Power Boxes

### Features

- Individual GFCI modules
- TYPE 3R metallic enclosure and heavy duty, abuse resistant legs
- Standard stab termination circuit breakers with gasketed lift cover

### Ordering Information

| Description                 | Product Type    | UPC          | Catalog Number |
|-----------------------------|-----------------|--------------|----------------|
| Spider Box, 50A, Twist Lock | Spider II Boxes | 783585370880 | SBTL1A         |

### Standards

UL 1640 cUL and CSA, UL 943

### Specifications

|                 |   |
|-----------------|---|
| Enclosure Type  | 3R, rainproof, suitable for use in damp locations |
| Code Compliance | NEC®, ANSI/NFPA 70                                |

### Performance


#### Environment

Moisture Resistance Indoor and outdoor wet and dry locations


### Online Resources

Customer Use Drawing  
eCatalog  
Installation Instructions

# HUBBELL

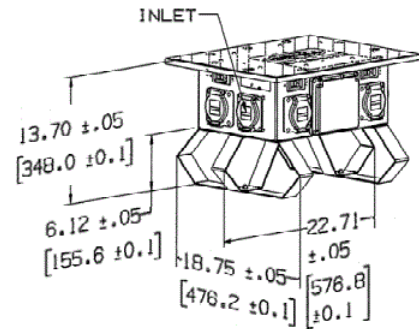

GFCI MODULES ON ALL  
20A INLETS/RECEPTACLES  
REPLACEMENT CAT NO. GFM20

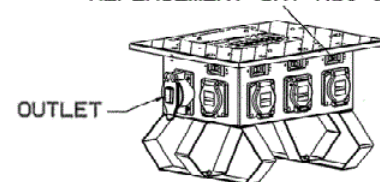

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

