

Single Pole Devices and Temporary Power

30A, 120/240V AC

Spider® II Temporary Power Boxes

Features

- Individual GFCI modules
- TYPE 3R metallic enclosure and heavy duty, abuse resistant legs
- Standard stab termination circuit breakers with gasketed lift cover

Ordering Information

Description	Product Type	UPC	Catalog Number
Spider Box, 30A, Straight Blade	Spider II Boxes	783585370897	SDSB1A

Standards

UL 1640 cUL and CSA, UL 943

Specifications

Enclosure Type	3R, rainproof, suitable for use in damp locations
Code Compliance	NEC®, ANSI/NFPA 70


Performance

Environment	Indoor and outdoor wet and dry locations
-------------	--


Online Resources

Customer Use Drawing
eCatalog
Installation Instructions

HUBBELL

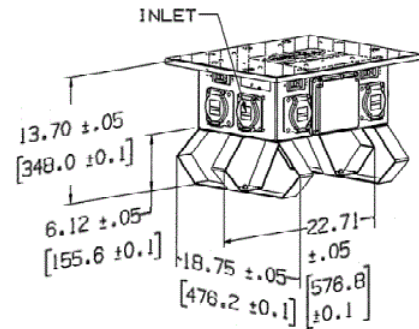

GFCI MODULES ON ALL
20A INLETS/RECEPTACLES
REPLACEMENT CAT NO. GFM20

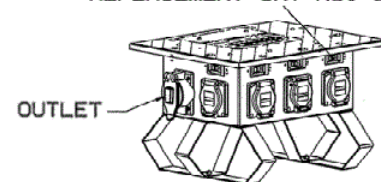

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

