

Straight Blade Devices

15 Amp, 125 Volt, 2-Pole, 3-Wire

SNAPConnect<sup>®</sup> Hospital Grade Receptacle



- Features
- Audible SNAP, indicates solid connection
  - Reduces installation time
  - Tamper-Resistant
  - Assembled in USA

Ordering Information

Description	Device Color	UPC Number	Catalog Number
Hospital Grade, Tamper-Resistant	Black	783585542898	SNAP2152BKTRA


- Listings
- UL Listed to UL498 File No. E2189  
Certified to CSA, C22.2, No. 42 File 288  
Fed. Spec. W-C-599  
NEMA<sup>®</sup> WD-6 Compliant

Specifications

Face	Nylon
Base	Nylon
Line Contact	Brass
Ground Contact	Brass

Performance

<b>Electrical</b>	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
<b>Mechanical</b>	
Product Identification	Ratings are a permanent part of the device
<b>Environmental</b>	
Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (without impact)

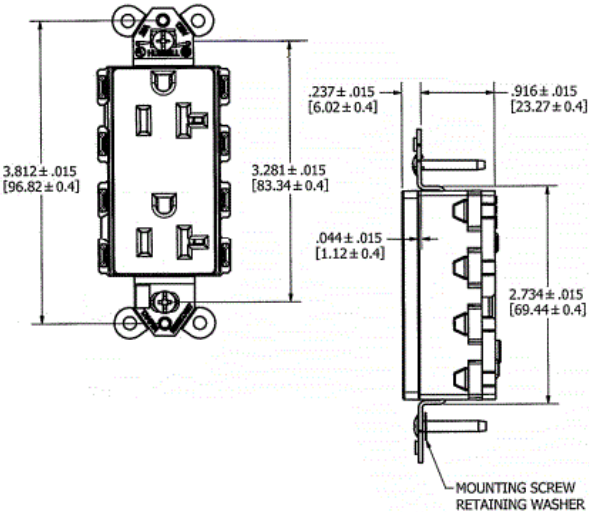

Complementary Products

Wallplate or Weatherproof Cover  
Opening

Online Resources

Customer Sales Drawing  
eCatalog  
Installation Instructions

