

Straight Blade Devices
 15A, 125V, 2 Pole, 3 Wire Grounding
 Extra Heavy Duty SNAPConnect®
 Receptacles

HUBBELL

Features

- Green LED Power Indicators
- Aesthetic Style Line® decorator design
- Audible SNAP, indicates solid connection
- Reduces installation time
- Fully insulated design

Ordering Information

Description	Device Color	UPC	Catalog Number
Specification grade, with Power Indicating LED, Style Line® decorator face.	Ivory	783585248714	SNAP2152IL



Listings

UL Listed to UL498 File No. E2186
 Certified to CSA, C22.2, No. 42 File 285
 Fed. Spec. W-C-596
 NEMA® WD-6 Compliant

Specifications

Face	Nylon
Base	PBT
Contacts	Brass
Mounting Strap	Galvanized steel
Auto Self-grounding Staple	Stainless steel
Mounting Screws	Zinc plated steel


Performance

Electrical
 Current Interrupting Receptacle certified for current interrupting at full rated current

Dielectric Voltage Withstands 2,000V minimum

Mechanical
 Product Identification Ratings are a permanent part of the device

Environmental
 Flammability UL 94V-2
 Operating Temperature Maximum continuous 75°C; minimum -40°C (without impact)

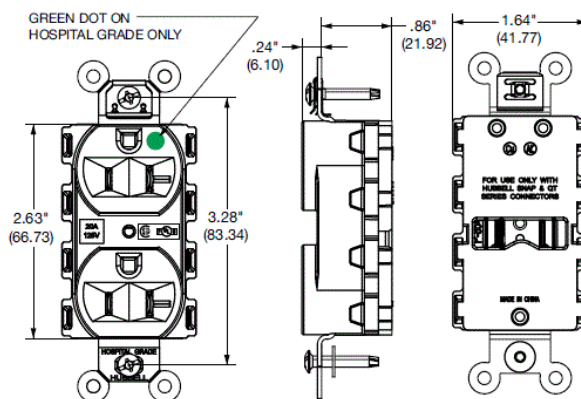

Accessories

Wallplate or Weatherproof Cover StyleLine® Decorator Opening

Resources

eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

