

Straight Blade Devices

20 Amp, 125 Volt, 2-Pole, 3-Wire

SNAPConnect[®] Extra Heavy Duty Receptacle



- Features
- Audible SNAP, indicates solid connection
 - Reduces installation time
 - Requires minimal box space
 - Assembled in USA

Ordering Information

| Description | Device Color | UPC Number | Catalog Number |
|-----------------|--------------|--------------|----------------|
| Standard Duplex | Ivory | 783585540184 | SNAP21621NA |

Listings

UL Listed to UL498 File No. E2271
Certified to CSA, C22.2, No. 42 File 370
Fed. Spec. W-C-681
NEMA[®] WD-6 Compliant

Specifications


| | |
|----------------|-------|
| Face | Nylon |
| Base | Nylon |
| Line Contact | Brass |
| Ground Contact | Brass |

Performance

| | |
|----------------------|--|
| Electrical | |
| Current Interrupting | Certified for current interrupting at full rated current |
| Dielectric Voltage | Withstands 2,000V minimum |

| | |
|------------------------|--|
| Mechanical | |
| Product Identification | Ratings are a permanent part of the device |

| | |
|-----------------------|---|
| Environmental | |
| Flammability | UL 94V-2 |
| Operating Temperature | Maximum continuous 75°C; minimum -40°C (without impact) |

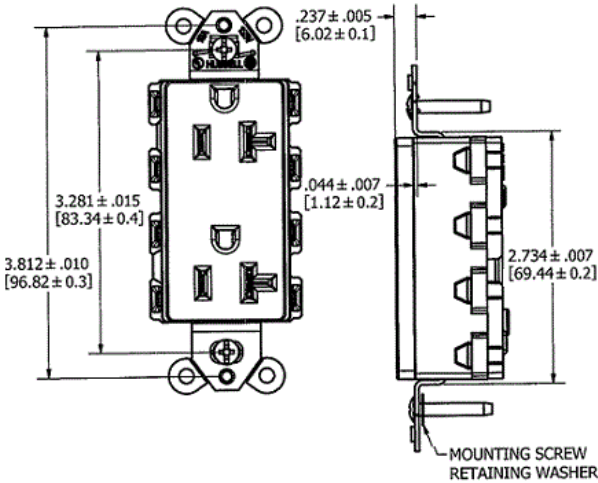

Complementary Products

Wallplate or Weatherproof Cover
Opening

Online Resources

Customer Sales Drawing
eCatalog
Installation Instructions

