

Straight Blade Devices  
 20A, 125V, 2 Pole, 3 Wire Grounding  
 Extra Heavy Duty SNAPConnect®  
 Receptacles

# HUBBELL

## Features

- Green LED Power Indicators
- Aesthetic Style Line® decorator design
- Audible SNAP, indicates solid connection
- Reduces installation time
- Fully insulated design

## Ordering Information

Description	Device Color	UPC	Catalog Number
Specification grade, with Power Indicating LED, Style Line® decorator face.	Red	783585248608	SNAP2162RL



## Listings

UL Listed to UL498 File No. E2186  
 Certified to CSA, C22.2, No. 42 File 285  
 Fed. Spec. W-C-596  
 NEMA® WD-6 Compliant

## Specifications

Face	Nylon
Base	PBT
Contacts	Brass
Mounting Strap	Galvanized steel
Auto Self-grounding Staple	Stainless steel
Mounting Screws	Zinc plated steel


## Performance

**Electrical**  
 Current Interrupting Receptacle certified for current interrupting at full rated current

Dielectric Voltage Withstands 2,000V minimum

**Mechanical**  
 Product Identification Ratings are a permanent part of the device

**Environmental**  
 Flammability UL 94V-2  
 Operating Temperature Maximum continuous 75°C; minimum -40°C (without impact)

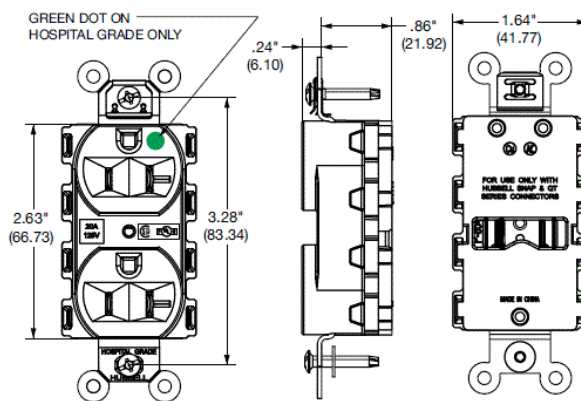

## Accessories

Wallplate or Weatherproof Cover StyleLine® Decorator Opening

## Resources

eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

