

Straight Blade Devices

20A, 125V, 2 Pole, 3 Wire Grounding

Extra Heavy Duty Hospital Grade SNAPConnect® Receptacle

Features

- Audible SNAP, indicates solid connection
- Reduces installation time
- Fully insulated design

Ordering Information

| Description | Device Color | UPC Number | Catalog Number |
|---------------------------------------|--------------|--------------|----------------|
| Hospital grade, Style Line® decorator | Gray | 783585247908 | SNAP2182GYA |

Listings

UL Listed to UL498 File No. E2186
CSA Certified
Fed. Spec. W-C-596
NEMA® WD-6 Compliant


Specifications

| | |
|---------------------------------|-------------------|
| Face | Nylon |
| Base | PBT |
| Power Contacts | Brass |
| Ground Contacts | Brass |
| Mounting Strap | Galvanized steel |
| Automatic Self-grounding Staple | Stainless steel |
| Mounting Screws | Zinc plated steel |

Performance

| | |
|------------------------|---|
| Electrical | |
| Current Interrupting | Receptacle certified for current interrupting at full rated current |
| Dielectric Voltage | Withstands 2,000V minimum |
| Mechanical | |
| Product Identification | Ratings are a permanent part of the device |
| Environmental | |
| Flammability | UL 94V-2 |
| Operating Temperature | Maximum continuous 75°C; minimum -40°C (without impact) |

HUBBELL

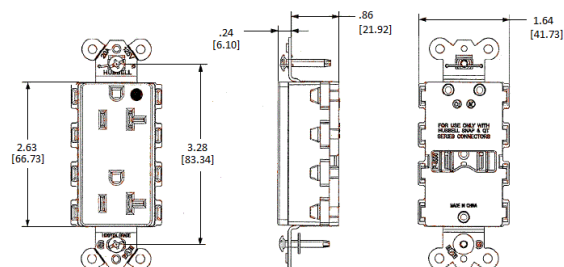

Complementary Products

Wallplate or Weatherproof Cover

StyleLine® Decorator Opening

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

