

Straight Blade Devices

20 Amp, 125 Volt, 2-Pole, 3-Wire

SNAPConnect[®] Hospital Grade Receptacle



Features

- Audible SNAP, indicates solid connection
- Reduces installation time
- Tamper-Resistant, LED Indicator
- Assembled in USA

Ordering Information

Description	Device Color	UPC Number	Catalog Number
Hospital Grade, Tamper-Resistant, Hospital Grade, Power Indicating LED	Brown	783585552439	SNAP2182LTRA

Listings


UL Listed to UL498 File No. E2342
Certified to CSA, C22.2, No. 42 File 441
Fed. Spec. W-C-752
NEMA[®] WD-6 Compliant

Specifications

Face	Nylon
Base	Nylon
Line Contact	Brass
Ground Contact	Brass

Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Product Identification	Ratings are a permanent part of the device
Environmental	
Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (without impact)

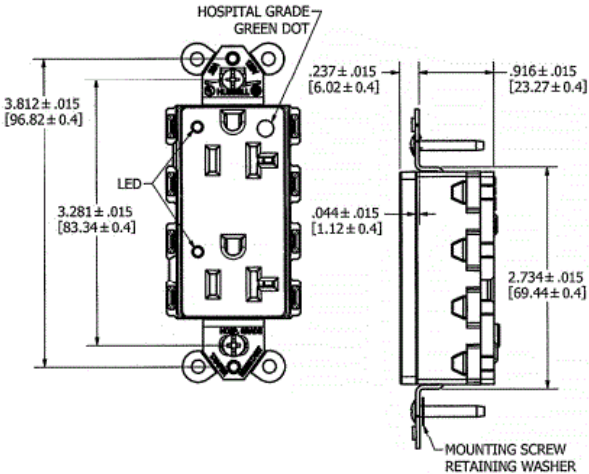

Complementary Products

Wallplate or Weatherproof Cover
Opening

Online Resources

Customer Sales Drawing
eCatalog
Installation Instructions

