

Straight Blade Devices

20 Amp, 125 Volt, 2-Pole, 3-Wire

SNAPConnect[®] Hospital Grade Receptacle

HUBBELL

Features

- Audible SNAP, indicates solid connection
- Reduces installation time
- Tamper-Resistant, LED Indicator
- Assembled in USA

Ordering Information

| Description | Device Color | UPC Number | Catalog Number |
|--|--------------|--------------|----------------|
| Hospital Grade, Tamper-Resistant, Hospital Grade, Power Indicating LED | Red | 783585552460 | SNAP2182RLTRA |



Listings

UL Listed to UL498 File No. E2346
Certified to CSA, C22.2, No. 42 File 445
Fed. Spec. W-C-756
NEMA[®] WD-6 Compliant

Specifications


| | |
|----------------|-------|
| Face | Nylon |
| Base | Nylon |
| Line Contact | Brass |
| Ground Contact | Brass |

Performance

| | |
|----------------------|--|
| Electrical | |
| Current Interrupting | Certified for current interrupting at full rated current |
| Dielectric Voltage | Withstands 2,000V minimum |

| | |
|------------------------|--|
| Mechanical | |
| Product Identification | Ratings are a permanent part of the device |

| | |
|-----------------------|---|
| Environmental | |
| Flammability | UL 94V-2 |
| Operating Temperature | Maximum continuous 75°C; minimum -40°C (without impact) |

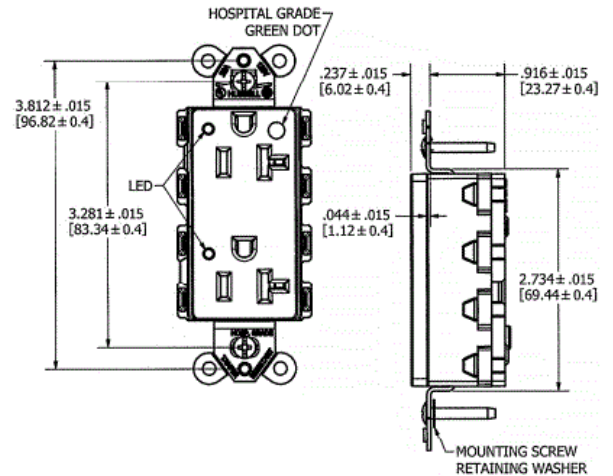

Complementary Products

Wallplate or Weatherproof Cover
Opening

Online Resources

Customer Sales Drawing
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

