

Straight Blade Devices

20 Amp, 125 Volt, 2-Pole, 3-Wire

SNAPConnect® Extra Heavy Duty Receptacle

HUBBELL

Features

- Audible SNAP, indicates solid connection
- Reduces installation time
- Tamper-Resistant, Split Circuit
- Assembled in USA

Ordering Information

Description	Device Color	UPC Number	Catalog Number
Standard Duplex	Ivory	783585552989	SNAP5362ISCTRA

Listings

UL Listed to UL498 File No. E2450  
Certified to CSA, C22.2, No. 42 File 549  
Fed. Spec. W-C-860  
NEMA® WD-6 Compliant

Specifications


Face	Nylon
Base	Nylon
Line Contact	Brass
Ground Contact	Brass

Performance

<b>Electrical</b>	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

<b>Mechanical</b>	
Product Identification	Ratings are a permanent part of the device

<b>Environmental</b>	
Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (without impact)

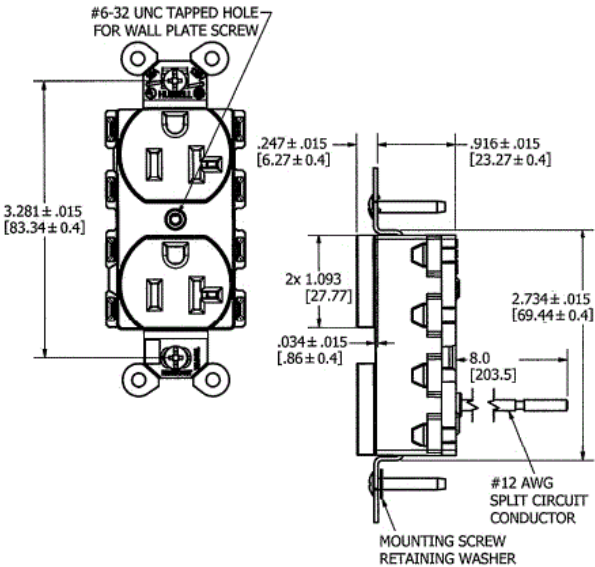

Complementary Products

Wallplate or Weatherproof Cover  
Opening

Online Resources

Customer Sales Drawing  
eCatalog  
Installation Instructions

