

Straight Blade Devices

20 Amp, 125 Volt, 2-Pole, 3-Wire

SNAPConnect® Extra Heavy Duty Receptacle



Features

- Audible SNAP, indicates solid connection
- Reduces installation time
- Surge supression, Tamper-Resistant, LED Indicator

Ordering Information

| Description | Device Color | UPC Number | Catalog Number |
|-----------------------------|--------------|--------------|----------------|
| Surge Protection Receptacle | Ivory | 783585252070 | SNAP5362IS |

Listings


UL Listed to UL498 File No. E2449
Certified to CSA, C22.2, No. 42 File 548
Fed. Spec. W-C-859
NEMA® WD-6 Compliant

Specifications

| | |
|----------------|-------|
| Face | Nylon |
| Base | Nylon |
| Line Contact | Brass |
| Ground Contact | Brass |

Performance

| Electrical | |
|------------------------|--|
| Current Interrupting | Certified for current interrupting at full rated current |
| Dielectric Voltage | Withstands 2,000V minimum |
| Mechanical | |
| Product Identification | Ratings are a permanent part of the device |
| Environmental | |
| Flammability | UL 94V-2 |
| Operating Temperature | Maximum continuous 75°C; minimum -40°C (without impact) |

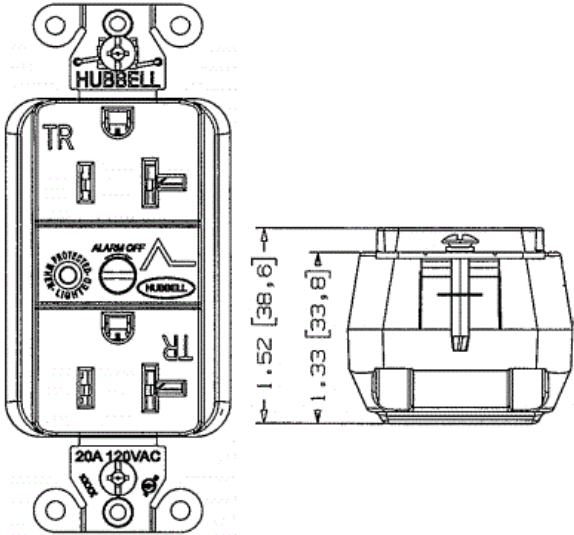

Complementary Products

Wallplate or Weatherproof Cover
Opening

Online Resources

Customer Sales Drawing
eCatalog
Installation Instructions

