

## SNAPConnect<sup>®</sup> Hospital Grade Receptacle

# HUBBELL


- Audible SNAP, indicates solid connection
- Reduces installation time
- Tamper-Resistant, Split Circuit
- Assembled in USA

<b>Description</b>	<b>Device Color</b>	<b>UPC Number</b>	<b>Catalog Number</b>
Hospital Grade, Tamper-Resistant, Split Circuit	Ivory	783585553528	SNAP8300ISCTRA



UL Listed to UL498 File No. E2539  
 Certified to CSA, C22.2, No. 42 File 638  
 Fed. Spec. W-C-949  
 NEMA® WD-6 Compliant

Face	Nylon
Base	Nylon
Line Contact	Brass
Ground Contact	Brass

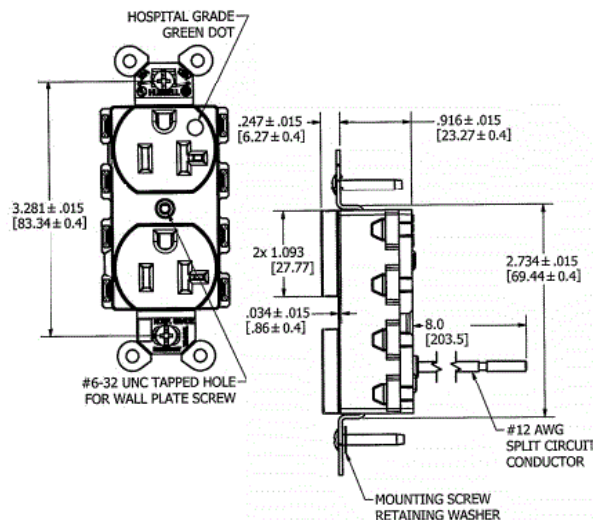

<b>Electrical</b>	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

Product Identification Ratings are a permanent part of the device

Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (without impact)

Wallplate or Weatherproof Cover  
Opening

Customer Sales Drawing  
eCatalog  
Installation Instructions

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

