

Straight Blade Devices

20 Amp, 125 Volt, 2-Pole, 3-Wire

SNAPConnect<sup>®</sup> Hospital Grade Receptacle



Features

- Audible SNAP, indicates solid connection
- Reduces installation time
- Requires minimal box space
- Assembled in USA

Ordering Information

Description	Device Color	UPC Number	Catalog Number
Hospital Grade, Standard Duplex	Lt Almond	783585540726	SNAP8300LANA

Listings

UL Listed to UL498 File No. E2542  
Certified to CSA, C22.2, No. 42 File 641  
Fed. Spec. W-C-952  
NEMA® WD-6 Compliant

Specifications


Face	Nylon
Base	Nylon
Line Contact	Brass
Ground Contact	Brass

Performance

<b>Electrical</b>	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

<b>Mechanical</b>	
Product Identification	Ratings are a permanent part of the device

<b>Environmental</b>	
Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (without impact)

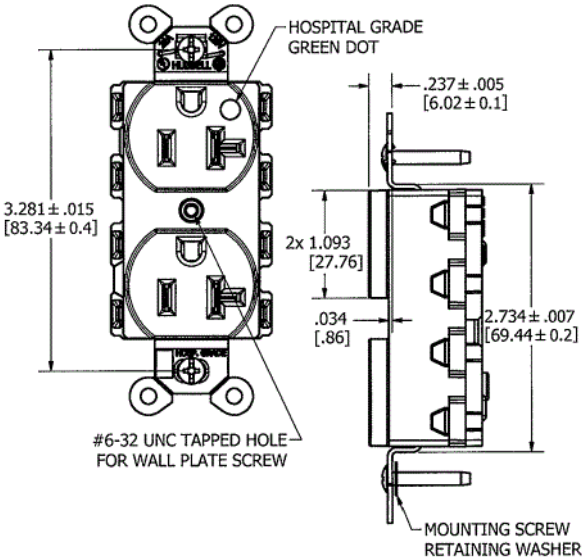

Complementary Products

Wallplate or Weatherproof Cover  
Opening

Online Resources

Customer Sales Drawing  
eCatalog  
Installation Instructions

