

Straight Blade Devices

20 Amp, 125 Volt, 2-Pole, 3-Wire

SNAPConnect<sup>®</sup> Hospital Grade Receptacle

HUBBELL

- Features
- Audible SNAP, indicates solid connection
  - Reduces installation time
  - Tamper-Resistant, LED Indicator
  - Assembled in USA

Ordering Information

Description	Device Color	UPC Number	Catalog Number
Hospital Grade, Tamper-Resistant, Hospital Grade, Power Indicating LED	Red	783585553603	SNAP8300RLTRA




Listings

UL Listed to UL498 File No. E2550  
Certified to CSA, C22.2, No. 42 File 649  
Fed. Spec. W-C-960  
NEMA® WD-6 Compliant

Specifications

Face	Nylon
Base	Nylon
Line Contact	Brass
Ground Contact	Brass

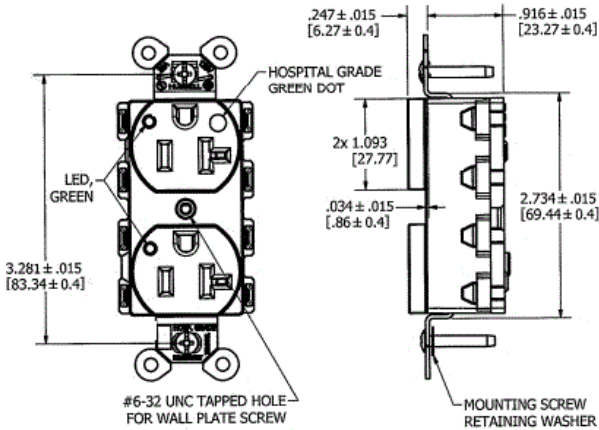

Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Product Identification	Ratings are a permanent part of the device
Environmental	
Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (without impact)

Complementary Products

Wallplate or Weatherproof Cover  
Opening

Online Resources

Customer Sales Drawing  
eCatalog  
Installation Instructions

