

Straight Blade Devices

20 Amp, 125 Volt, 2-Pole, 3-Wire

SNAPConnect® Hospital Grade Receptacle



- Features
- Audible SNAP, indicates solid connection
  - Reduces installation time
  - Single Receptacle

Ordering Information


Description	Device Color	UPC Number	Catalog Number
Hospital Grade, Standard Duplex	Lt Almond	783585557335	SNAP8310LA



- Listings
- UL Listed to UL498 File No. E2569  
Certified to CSA, C22.2, No. 42 File 668  
Fed. Spec. W-C-979  
NEMA® WD-6 Compliant

Specifications

Face	Nylon
Base	Nylon
Line Contact	Brass
Ground Contact	Brass

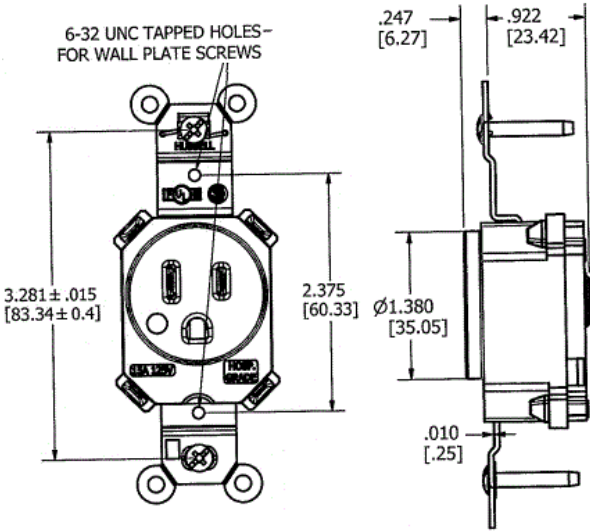

Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

Mechanical	
Product Identification	Ratings are a permanent part of the device

Environmental	
Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (without impact)

Complementary Products

Wallplate or Weatherproof Cover  
Opening

Online Resources

Customer Sales Drawing  
eCatalog  
Installation Instructions

