

Straight Blade Devices 15A, 125V, 2 Pole, 3 Wire Grounding USB Charger Receptacles

HUBBELL

Features

- High Power 5 Amp, 5 Volt USB Output
- Two Type C USB Ports
- Tamper Resistant Commercial Grade Duplex Compatible
- USB Ports Rated 10,000 Cycles

Ordering Information


| Description | Color | UPC Number | Catalog Number |
|--|-------|--------------|----------------|
| Tamper Resistant 15A/125V Duplex, 5 Amp, 5 Volts USB Ports | Ivory | 883778307447 | USB15C5I |

Listings

cULus Listed to UL498, UL1310

Specifications

| | |
|-----------------|-------------------------|
| Face | RTP |
| Base | RTP |
| LED | Green Indicator |
| Contacts | Plated Steel |
| Clamp | Plated Steel |
| Terminal Screws | Plated Steel |
| Mounting Strap | .040" Zinc Plated Steel |
| Mounting Screws | Zinc Plated Steel |
| USB Port | Stainless Steel |

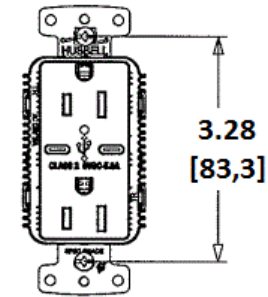

15A STANDARD
GRADE DEVICE

Online Resources

eCatalog

Performance

Electrical

| | |
|----------------------|---|
| Current Interrupting | Certified for current interrupting at full rated current |
| Dielectric Voltage | Withstands 2,000V minimum Complies with USB BC1.2 Battery Charging and 3.0 Power Delivery Specifications |

Mechanical

| | |
|-------------------------|--|
| Product Identification | Ratings are a permanent part of the device |
| Terminal Accommodation | #14-#10 AWG copper stranded or solid conductor only |
| Terminal Identification | Terminals identified in accordance with UL 498 and CSA |
| USB Ports | Stainless steel rated for 10,000 plug insertions and removal |

Environmental

| | |
|-----------------------|---|
| Flammability | UL 94V-2 |
| Operating Temperature | Maximum continuous 75°C, minimum -40°C (w/o impact) |

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

