

# Straight Blade Devices 15A, 125V, 2 Pole, 3 Wire Grounding Hospital Grade USB Charger Receptacles

## Features

- High Power 5 Amp, 5 Volt USB Output
- Two Type A USB Ports
- Tamper Resistant Hospital Grade Duplex Compatible
- USB Ports Rated 10,000 Cycles

## Ordering Information

| Description                                                                | Color | UPC Number   | Catalog Number |
|----------------------------------------------------------------------------|-------|--------------|----------------|
| Hospital Grade, Tamper Resistant 15A/125V Duplex, 5 Amp, 5 Volts USB Ports | White | 883778307034 | USB8200A5W     |

## Listings

cULus Listed to UL498, UL1310

## Specifications

|                 |                         |
|-----------------|-------------------------|
| Face            | RTP                     |
| Base            | RTP                     |
| LED             | Green Indicator         |
| Contacts        | Plated Steel            |
| Clamp           | Plated Steel            |
| Terminal Screws | Plated Steel            |
| Mounting Strap  | .040" Zinc Plated Steel |
| Mounting Screws | Zinc Plated Steel       |
| USB Port        | Stainless Steel         |

## Performance

### Electrical

|                      |                                                                                                             |
|----------------------|-------------------------------------------------------------------------------------------------------------|
| Current Interrupting | Certified for current interrupting at full rated current                                                    |
| Dielectric Voltage   | Withstands 2,000V minimum<br>Complies with USB BC1.2 Battery Charging and 3.0 Power Delivery Specifications |

### Mechanical

|                         |                                                              |
|-------------------------|--------------------------------------------------------------|
| Product Identification  | Ratings are a permanent part of the device                   |
| Terminal Accommodation  | #14-#10 AWG copper stranded or solid conductor only          |
| Terminal Identification | Terminals identified in accordance with UL 498 and CSA       |
| USB Ports               | Stainless steel rated for 10,000 plug insertions and removal |

### Environmental


|                       |                                                     |
|-----------------------|-----------------------------------------------------|
| Flammability          | UL 94V-2                                            |
| Operating Temperature | Maximum continuous 75°C, minimum -40°C (w/o impact) |

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

# HUBBELL

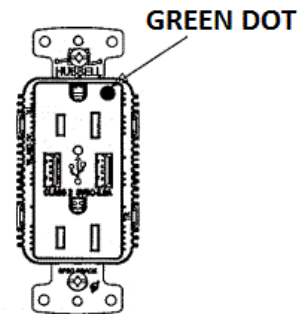

**15A HOSPITAL  
GRADE DEVICE**

## Online Resources

eCatalog

