

Straight Blade Devices
15A, 125V, 2 Pole, 3 Wire Grounding
USB Charger Tamper-Resistant Hospital
Grade Receptacles

Features

- Two USB ports 3 Amp, 5V DC, type A, class 2.0
- Tamper-Resistant decorator duplex receptacle
- Green LED indicator to show USB power available
- Compatible with USB 1.1/2.0/3.0 devices, including Apple® products

Ordering Information

| Description | Device Color | UPC | Catalog Number |
|---|--------------|--------------|----------------|
| USB 15A 125V AC Charger Tamper-Resistant receptacle, Two USB Type 2.0 ports 3 Amp, 5 Volt DC | Black | 883778304958 | USB8200BK |

Listings

cULus listed to UL498 and UL1310 Hospital Grade
NEMA® WD-6 Compliant


Specifications

| | |
|-----------------|-------------------------|
| Face | RTP |
| Base | RTP |
| LED | Green Indicator |
| Contacts | Brass |
| Clamp | Plated steel |
| Terminal Screws | Plated steel |
| Mounting Strap | .040" Zinc plated steel |
| Mounting Screws | Zinc plated steel |

Performance

| | |
|-------------------------|--|
| Electrical | |
| Current Interrupting | Certified for current interrupting at full rated current |
| Dielectric Voltage | Withstands 2,000V minimum |
| Mechanical | |
| Product Identification | Ratings are a permanent part of the device |
| Terminal Accommodation | #14-#10 AWG copper stranded or solid conductor only |
| Terminal Identification | Terminals identified in accordance with UL 498 and CSA |
| USB Port | Stainless steel Rated for 10,000 plug insertions and removal |
| Environmental | |
| Flammability | UL 94V-2 |
| Operating Temperature | Maximum continuous 75°C; minimum -40°C (w/o impact) |

HUBBELL

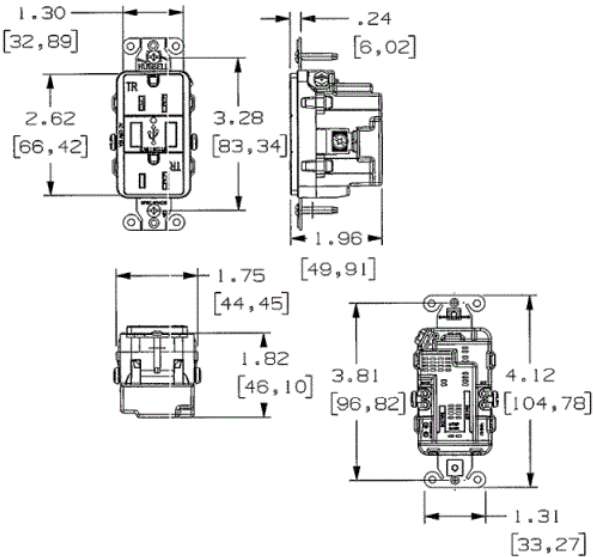

Accessories

Wallplate or Weatherproof Cover StyleLine® Decorator Opening

Resources

Customer Use Drawing
eCatalog

