

Straight Blade Devices
15A, 125V, 2 Pole, 3 Wire Grounding
USB Charger Tamper-Resistant Hospital
Grade Receptacles

HUBBELL

Features

- Two USB ports 3 Amp, 5V DC, type A, class 2.0
- Tamper-Resistant decorator duplex receptacle
- Green LED indicator to show USB power available
- Compatible with USB 1.1/2.0/3.0 devices, including Apple® products

Ordering Information

Description	Device Color	UPC	Catalog Number
USB 15A 125V AC Charger Tamper-Resistant receptacle, Two USB Type 2.0 ports 3 Amp, 5 Volt DC	Light Almond	883778304972	USB8200LA

Listings

cULus listed to UL498 and UL1310 Hospital Grade
NEMA® WD-6 Compliant

Specifications

Face	RTP
Base	RTP
LED	Green Indicator
Contacts	Brass
Clamp	Plated steel
Terminal Screws	Plated steel
Mounting Strap	.040" Zinc plated steel
Mounting Screws	Zinc plated steel

Performance

Electrical


Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

Mechanical

Product Identification	Ratings are a permanent part of the device
Terminal Accommodation	#14-#10 AWG copper stranded or solid conductor only
Terminal Identification	Terminals identified in accordance with UL 498 and CSA
USB Port	Stainless steel Rated for 10,000 plug insertions and removal

Environmental

Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (w/o impact)

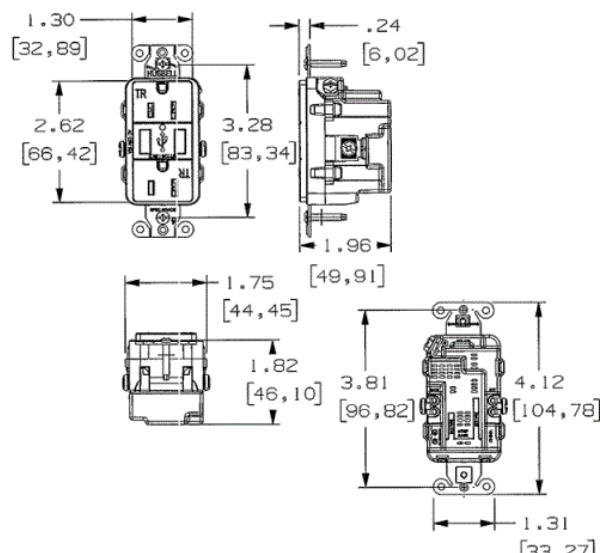

Accessories

Wallplate or Weatherproof Cover StyleLine® Decorator Opening

Resources

Customer Use Drawing
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.