

Straight Blade Devices  
20A, 125V, 2 Pole, 3 Wire Grounding  
Hospital Grade USB Charger  
Receptacles

Features

- High Power 5 Amp, 5 Volt USB Output
- Combination Ports, One Type A, One Type C
- Tamper Resistant Hospital Grade Duplex Compatible
- USB Ports Rated 10,000 Cycles

Ordering Information

| Description                                                                | Color        | UPC Number   | Catalog Number |
|----------------------------------------------------------------------------|--------------|--------------|----------------|
| Hospital Grade, Tamper Resistant 20A/125V Duplex, 5 Amp, 5 Volts USB Ports | Light Almond | 883778307393 | USB8300AC5LA   |

Listings

cULus Listed to UL498, UL1310


Specifications

|                 |                         |
|-----------------|-------------------------|
| Face            | RTP                     |
| Base            | RTP                     |
| LED             | Green Indicator         |
| Contacts        | Plated Steel            |
| Clamp           | Plated Steel            |
| Terminal Screws | Plated Steel            |
| Mounting Strap  | .040" Zinc Plated Steel |
| Mounting Screws | Zinc Plated Steel       |
| USB Port        | Stainless Steel         |

Performance

|                         |                                                                                                             |
|-------------------------|-------------------------------------------------------------------------------------------------------------|
| <b>Electrical</b>       |                                                                                                             |
| Current Interrupting    | Certified for current interrupting at full rated current                                                    |
| Dielectric Voltage      | Withstands 2,000V minimum<br>Complies with USB BC1.2 Battery Charging and 3.0 Power Delivery Specifications |
| <b>Mechanical</b>       |                                                                                                             |
| Product Identification  | Ratings are a permanent part of the device                                                                  |
| Terminal Accommodation  | #14-#10 AWG copper stranded or solid conductor only                                                         |
| Terminal Identification | Terminals identified in accordance with UL 498 and CSA                                                      |
| USB Ports               | Stainless steel rated for 10,000 plug insertions and removal                                                |
| <b>Environmental</b>    |                                                                                                             |
| Flammability            | UL 94V-2                                                                                                    |
| Operating Temperature   | Maximum continuous 75°C, minimum -40°C (w/o impact)                                                         |

HUBBELL

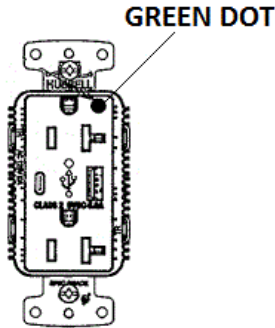

20A HOSPITAL  
GRADE DEVICE

Online Resources

eCatalog

