




ACC-R4, Rail Cable Clip, Up to 4 0.29" PV wires

By WILEY
Catalog # ACC-R4

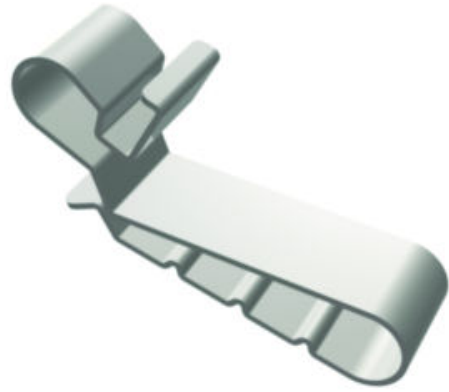

Rail Cable Clips.

Features

304 Stainless Steel Clips that install on the rail, channel, or slot

General

Application	1 to 4 PV wires,Wire Diameter Range: 4.1mm - 6.5mm per each cable
Catalog Number	ACC-R4
Construction Material - Main	Nylon
EU RoHS Indicator	Contact Manufacturer
Item Type	3B
Material	304 Stainless Steel
Mounting Method	Racking: Unirac, Ironrigde, Everest or similar rack profiles
Trade Name	WILEY
Type	Cable Clips
UPC	781810537091
UPC 12 Digit	7818105370911

Dimensions

Dimension - Thread Size -

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	N
Certification - UL Recognized	N
Certification - cULus	Yes
Certified Listed	UL1565
Industry Standard(s)	UL1565
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity 4000

Product Assets

- [Catalogs - Wiley Wire Management Guide](#)
- [Catalogs - BURNDY Master Catalog - Section E4 - Wiley Grounding](#)
- [Catalogs - BURNDY Master Catalog - Section G - Wire Management](#)
- [Customer Notices - Prop 65 Notice](#)
- [Sales Drawings - 30023996](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
WLY_CA-ACCR4-SPEC-EN | REV 6/2024