

**Features**

- Flip top link design
- Fiberglass reinforced nylon construction
- Highly wear resistant design provides corrosion resistance

**Ordering Information**



<b>Color</b> Black	<b>UPC</b> 783585343662	<b>Catalog Number</b> HCT25347K
-----------------------	----------------------------	------------------------------------

**Specifications**

Application	Cable and Hose Carrier
Depth	1.75
Width	6.6 in
Wire Size	5.940"

**Performance**

<b>Environmental</b>	
Max. Operating Speed	600 FPM (feet per minute), 180 MPM (meters per minute)
Max. Unsupported Travel Distance	HCT16 Series without sag 9 ft. (2.8 m) with sag 10.5 ft. (3.2 m); HCT25 Series without sag 13.5 ft. (4.1 m) with sag 17 ft. (5.2 m)
Operating Temperature	Continuous +20°F to +100°F (-7°C to 38°C); Intermittent* -40°F to +220°F (-40°C to 104°C)

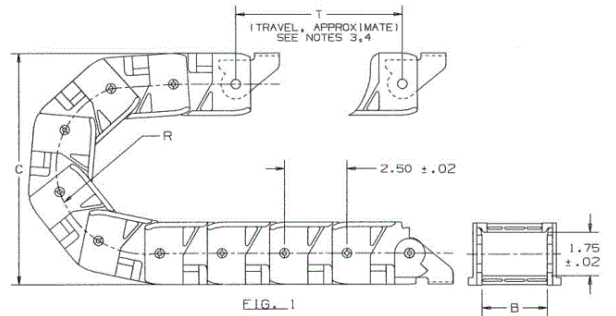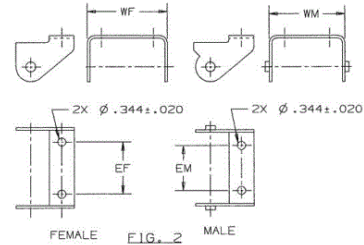

**Online Resources**

- Customer Sales Drawings
- eCatalog
- Installation Instructions