

TradeSelect

15 A, 125 VAC, 2-Pole, 3-Wire Grounding

Single Receptacle, Tamper Resistant

# HUBBELL

## Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

## Ordering Information

<b>Color</b> Black	<b>UPC</b> 883778301889	<b>Catalog Number</b> RR151BKTR
-----------------------	----------------------------	------------------------------------


## Specifications

NEMA Rating	5-15R
Wire Size	#14 AWG to #12 AWG
Wattage	1875
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Tamper Resistant- Self Grounding
Phase	Single Phase

## Performance

<b>Environmental</b> Operating temperature	20°C to 60°C
---	--------------

<b>Mechanical</b> Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only
-------------------------------	--

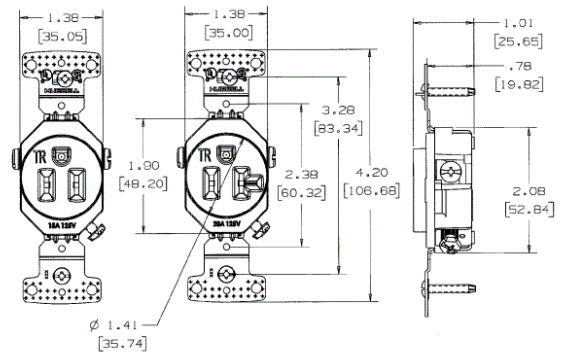

## Online Resources

Customer Sales Drawings  
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

