

TradeSelect

15 A, 125 V, 2-Pole, 3-Wire

Receptacles, Residential Grade, Tamper
Resistant Clock Hanger

HUBBELL

Ordering Information


Color	UPC	Catalog Number
Stainless Steel	883778302176	RR151CHSSTR

Listings

UL Listed

Specifications

NEMA Rating	5-15R
Wire Size	#14 AWG to #12 AWG
Wattage	1875
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Clock Hanger Receptacle
Phase	Single Phase

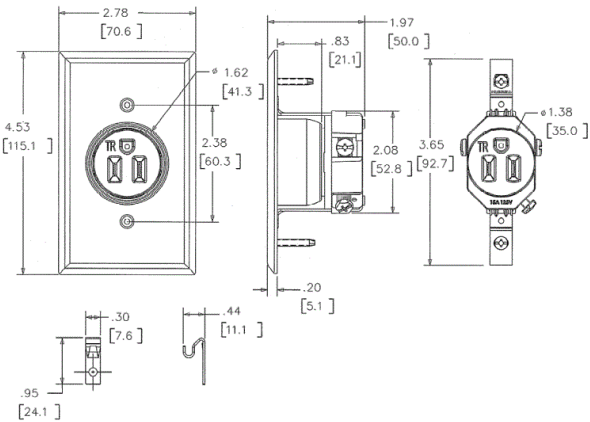

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

