

TradeSelect

**15 A, 125 VAC, 2-Pole, 3-Wire Grounding
Single Receptacle, Self Grounding**

HUBBELL

Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

Ordering Information

Color Gray	UPC 883778110610	Catalog Number RR151GY
----------------------	----------------------------	----------------------------------

Specifications


Wattage	1875
NEMA Rating	5-15R
Wire Size	#14 AWG to #12 AWG
Special Features	Self Grounding
Phase	Single Phase
Environmental Conditions	Indoor Dry Unless Protected By Additional Means

Performance

Environmental Operating temperature	20°C to 60°C
---	--------------

Mechanical

Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only
----------	--

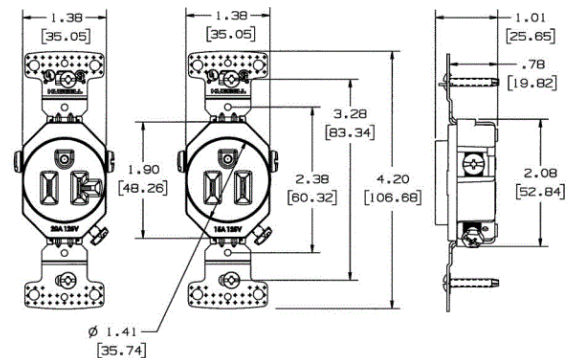

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

