

TradeSelect

15 A, 125 VAC, 2-Pole, 3-Wire Grounding

## Receptacles, Residential Grade, Tamper Resistant Single

### Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

### Ordering Information

|                |                     |                            |
|----------------|---------------------|----------------------------|
| Color<br>White | UPC<br>883778301933 | Catalog Number<br>RR151WTR |
|----------------|---------------------|----------------------------|

### Specifications

|                          |   |
|--------------------------|---|
| NEMA Rating              | 5-15R   |
| Wire Size                | #14 AWG to #12 AWG                              |
| Wattage                  | 1875  |
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means |
| Special Features         | Tamper Resistant- Self Grounding                |
| Phase                    | Single Phase                                    |


### Performance

|  |              |
|--|--------------|
| Environmental<br>Operating temperature | 20°C to 60°C |
|--|--------------|

### Mechanical

|          |  |
|----------|--|
| Terminal | Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only |
|----------|--|

# HUBBELL

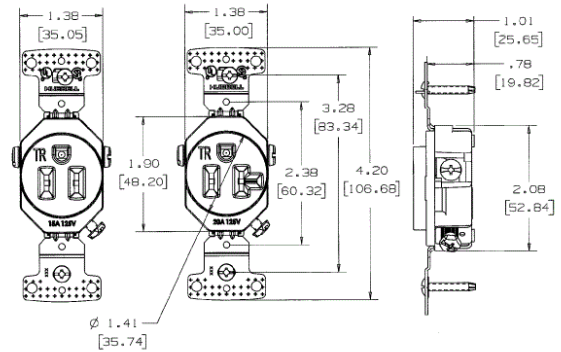

### Online Resources

Customer Sales Drawings  
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

