

TradeSelect

15 A, 250V kV, 2-Pole, 3-Wire Grounding

Receptacles, Residential Grade, Single


HUBBELL

- Features
- Smooth indented face appearance
 - Multiple-drive Slot/Phillips/Robertson head screws
 - Tough thermoplastic ultrasonically welded cover and base

Ordering Information		
Color	UPC	Catalog Number
Ivory	883778300530	RR155I

Specifications	
NEMA Rating	6-15R
Wire Size	#14 AWG to #12 AWG
Wattage	3750
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Self Grounding
Phase	Single Phase

Performance	
Environmental	
Operating temperature	20°C to 60°C
Mechanical	
Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only

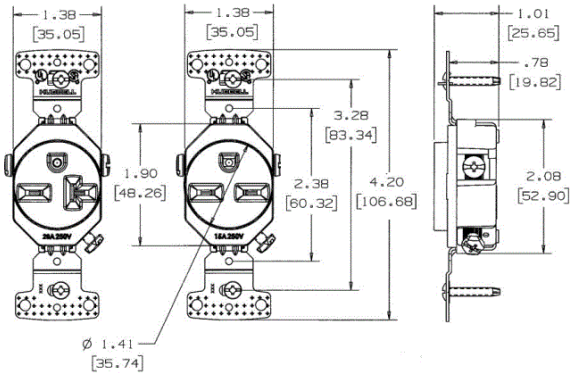

- Online Resources
- Customer Sales Drawings
 - eCatalog
 - Installation Instructions

