

TradeSelect

**15 A, 125 VAC, 2-Pole, 3-Wire Grounding
Receptacles, Residential Grade, Duplex**

HUBBELL

Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

Ordering Information


| | | |
|-----------------------|----------------------------|--------------------------------|
| Color Ivory | UPC 883778100024 | Catalog Number RR15I |
|-----------------------|----------------------------|--------------------------------|

Specifications

| | |
|--------------------------|---|
| NEMA Rating | 5-15R |
| Wire Size | #14 AWG to #12 AWG |
| Wattage | 1875 |
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means |
| Special Features | Self Grounding |
| Phase | Single Phase |

Performance

| | |
|-----------------------|--|
| Environmental | |
| Operating temperature | 20°C to 60°C |
| Mechanical | |
| Terminal | Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only |

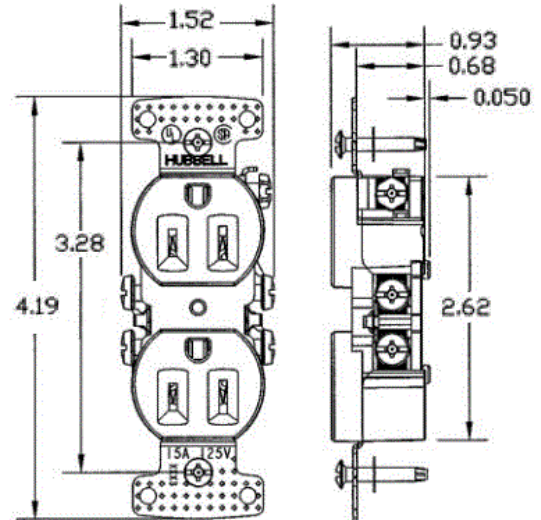

Online Resources

Customer Sales Drawings
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

