

TradeSelect

15 A, 125 VAC, 2-Pole, 3-Wire Grounding

Receptacles, Residential Grade, Tamper Resistant Duplex

- Features
- Smooth indented face appearance
 - Tough thermoplastic ultrasonically welded cover and base
 - Elongated strap with continuous plaster ears to secure device

Ordering Information		
Color	UPC	Catalog Number
White	883778301612	RR15QWTR


Listings

CSA Certified;UL Listed E2186

Specifications	
Wattage	1875
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Tamper Resistant- Self Grounding, Quick Thread
Phase	Single Phase
NEMA Rating	5-15R
Wire Size	#14 AWG to #12 AWG

Performance	
Environmental	
Operating temperature	20°C to 60°C
Mechanical	
Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only

HUBBELL

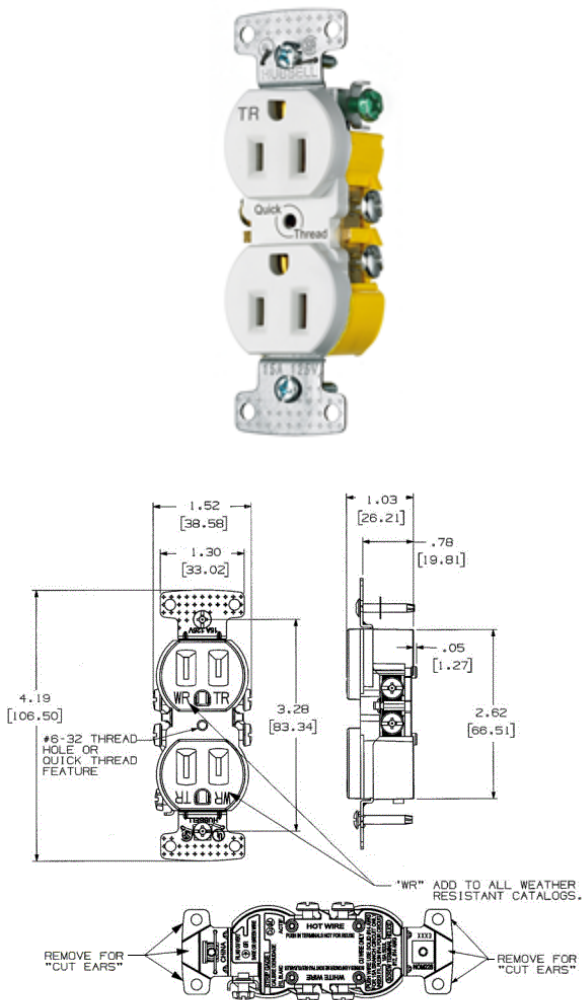

Online Resources

Customer Sales Drawings

eCatalog

