

TradeSelect

**15 A, 125 VAC, 2-Pole, 3-Wire Grounding  
Receptacles, Residential Grade, Duplex**

# HUBBELL

### Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

### Ordering Information


<b>Color</b> Brown	<b>UPC</b> 883778100017	<b>Catalog Number</b> RR15
-----------------------	----------------------------	-------------------------------

### Specifications

NEMA Rating	5-15R
Wire Size	#14 AWG to #12 AWG
Wattage	1875
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Self Grounding
Phase	Single Phase

### Performance

<b>Environmental</b>	
Operating temperature	20°C to 60°C
<b>Mechanical</b>	
Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only

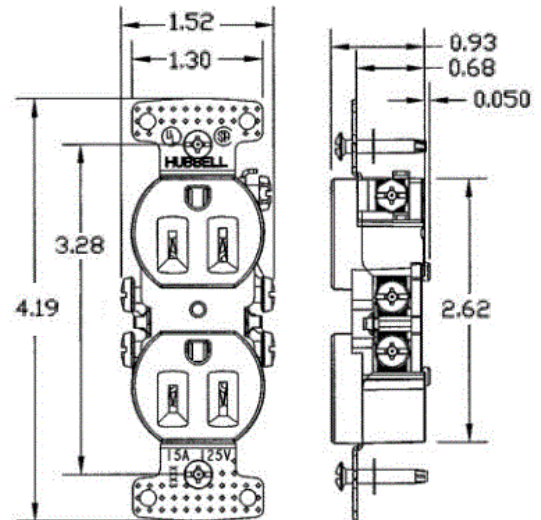

### Online Resources

Customer Sales Drawings  
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

