

TradeSelect

20 A, 125 VAC, 2-Pole, 3-Wire Grounding

Single Receptacle, Tamper Resistant

- Features
- Smooth indented face appearance
 - Multiple-drive Slot/Phillips/Robertson head screws
 - Tough thermoplastic ultrasonically welded cover and base

Ordering Information

Color	UPC	Catalog Number
Black	883778301957	RR201BKTR

Specifications

NEMA Rating	5-20R
Wire Size	#12 AWG to #10 AWG
Wattage	2500
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Tamper Resistant- Self Grounding
Phase	Single Phase


Performance

20°C to 60°C	
Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only

Environmental

Operating temperature

HUBBELL

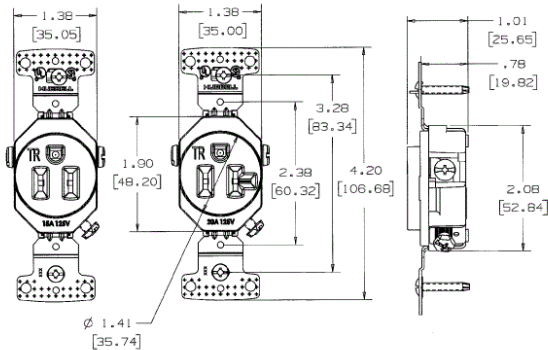

Online Resources

Customer Sales Drawings

eCatalog

