

TradeSelect

20 A, 125 VAC, 2-Pole, 3-Wire Grounding

Single Receptacle, Weather and Tamper Resistant

- Features
- Smooth indented face appearance
 - Multiple-drive Slot/Phillips/Robertson head screws
 - Tough thermoplastic ultrasonically welded cover and base


Ordering Information		
Color	UPC	Catalog Number
Black	883778302930	RR201BKWRT

Specifications	
NEMA Rating	5-20R
Wire Size	#12 AWG to #10 AWG
Wattage	2500
Environmental Conditions	Weather Resistant
Special Features	Weather and Tamper Resistant- Self Grounding
Phase	Single Phase

Performance	
20°C to 60°C	
Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only

Environmental
Operating temperature

HUBBELL

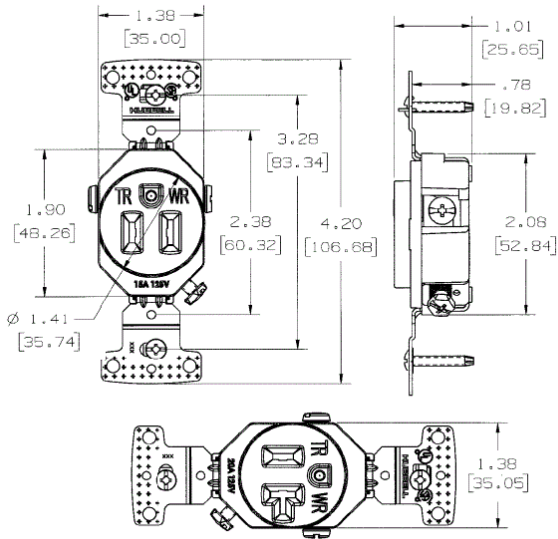

- Online Resources
- Customer Sales Drawings
 - eCatalog
 - Installation Instructions

