

TradeSelect

20 A, 125 VAC, 2-Pole, 3-Wire Grounding

## Residential Grade, Receptacles, Tamper Resistant Single

### Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

### Ordering Information

Color Ivory	UPC 883778301988	Catalog Number RR201ITR
----------------	---------------------	----------------------------

### Specifications

NEMA Rating	5-20R
Wire Size	#12 AWG to #10 AWG
Wattage	2500
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Tamper Resistant- Self Grounding
Phase	Single Phase


### Performance

Environmental Operating temperature	20°C to 60°C
--	--------------

### Mechanical

Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only
----------	--

# HUBBELL

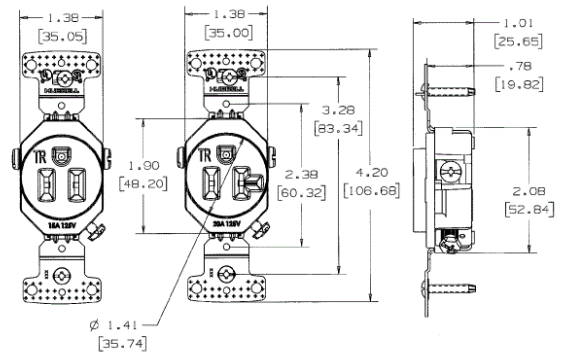

### Online Resources

Customer Sales Drawings  
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

