

TradeSelect

20 A, 125 VAC, 2-Pole, 3-Wire Grounding

Residential Grade, Receptacles, Single



- Features
- Smooth indented face appearance
  - Multiple-drive Slot/Phillips/Robertson head screws
  - Tough thermoplastic ultrasonically welded cover and base

Ordering Information


Color	UPC	Catalog Number
Light Almond	883778119262	RR201LA

Specifications

NEMA Rating	5-20R
Wire Size	#12 AWG to #10 AWG
Wattage	2500
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Self Grounding
Phase	Single Phase

Performance

Environmental	
Operating temperature	20°C to 60°C
Mechanical	
Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only

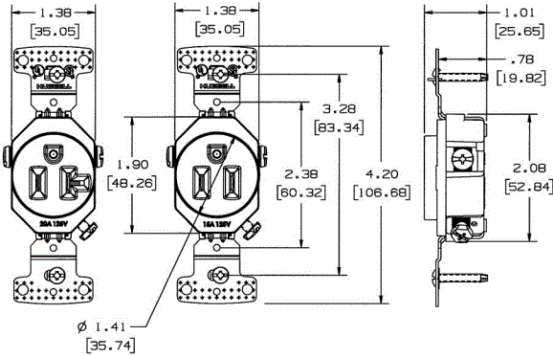

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

