

TradeSelect

20 A, 125 VAC, 2-Pole, 3-Wire Grounding

Residential Grade, Receptacles, Tamper Resistant Single

Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

Ordering Information

Color	UPC	Catalog Number
White	883778302008	RR201WTR

Specifications

NEMA Rating	5-20R
Wire Size	#12 AWG to #10 AWG
Wattage	2500
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Special Features	Tamper Resistant- Self Grounding
Phase	Single Phase


Performance

Environmental	
Operating temperature	20°C to 60°C

Mechanical

Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only
----------	--

HUBBELL

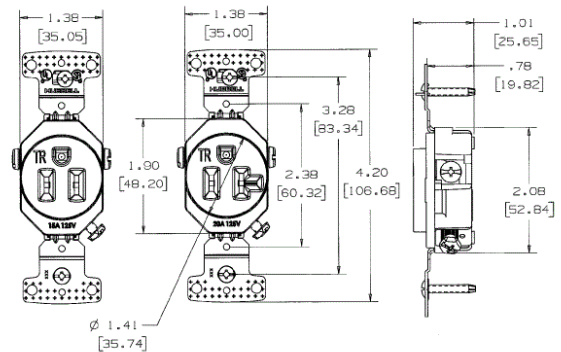

Online Resources

Customer Sales Drawings
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

