

TradeSelect

20 A, 125 VAC, 2-Pole, 3-Wire Grounding

Residential Grade, Receptacles, Single

# HUBBELL

## Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

## Ordering Information

|                       |                            |                                 |
|-----------------------|----------------------------|---------------------------------|
| <b>Color</b><br>White | <b>UPC</b><br>883778100277 | <b>Catalog Number</b><br>RR201W |
|-----------------------|----------------------------|---------------------------------|

## Specifications


|                          |   |
|--------------------------|---|
| NEMA Rating              | 5-20R   |
| Wire Size                | #12 AWG to #10 AWG                              |
| Wattage                  | 2500  |
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means |
| Special Features         | Self Grounding                                  |
| Phase                    | Single Phase                                    |

## Performance

|   |              |
|---|--------------|
| <b>Environmental</b><br>Operating temperature | 20°C to 60°C |
|---|--------------|

## Mechanical

|          |  |
|----------|--|
| Terminal | Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only |
|----------|--|

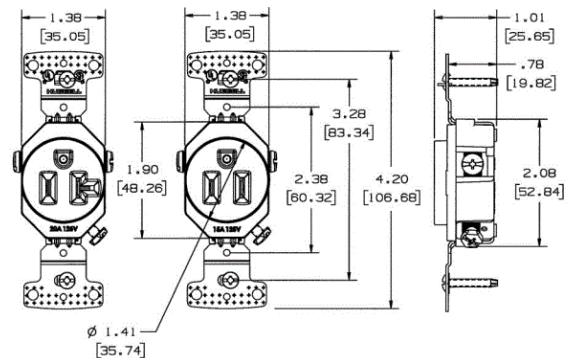

## Online Resources

Customer Sales Drawings  
eCatalog  
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

