

TradeSelect

20 A, 250V kV, 2-Pole, 3-Wire Grounding

Single Receptacle, Weather Resistant

HUBBELL

Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

Ordering Information

Color	UPC	Catalog Number
Brown	883778302787	RR205WR


Specifications

NEMA Rating	6-20R
Wire Size	#12 AWG to #10 AWG
Wattage	5000
Environmental Conditions	Weather Resistant
Special Features	Weather Resistant- Self Grounding
Phase	Single Phase

Performance

Environmental	
Operating temperature	20°C to 60°C

Mechanical	
Terminal	Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only

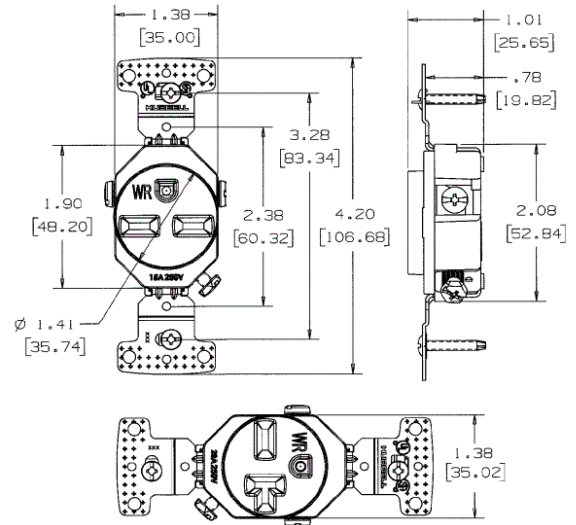

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

