

TradeSelect

20 A, 125 VAC, 2-Pole, 3-Wire Grounding

Single Decorator Receptacle, Self Grounding

HUBBELL

Ordering Information


Color
Black

UPC
883778100406

Catalog Number
RRD201BK

Specifications

NEMA Rating 5-20R
Wire Size #14 AWG to #12 AWG
Wattage 2500
Environmental Conditions Indoor Dry Unless Protected By Additional Means
Special Features Self Grounding
Phase Single Phase

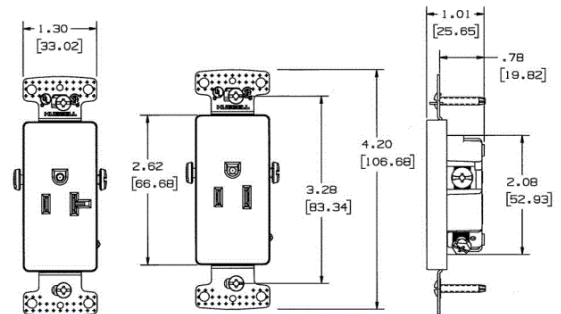

CATALOG NO'S	CONFIG	RATING
RRD15I	[Symbol: Two vertical slots, ground pin]	15A 125V
RRD15I I		
RRD15IW		
RRD15IGY		
RRD15IBK		
RRD15IAL		
RRD15ILA	NEMA 5-15R	
RRD20I	[Symbol: Two vertical slots, ground pin]	20A 125V
RRD20I I		
RRD20IW		
RRD20IGY		
RRD20IBK		
RRD20IAL		
RRD20ILA	NEMA 5-20R	

Online Resources

[Customer Sales Drawings](#)
[eCatalog](#)
[Installation Instructions](#)

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

